

2-Door Floor-Stand 3-Point Latches Type 4X, 62x60x18, SS Type 316

CATALOG NUMBER

A62H6018SS6LP3PT



These two-door enclosures provide industry-leading protection for large components or complex mounting configurations in highly corrosive environments. Three-point latching with the HOFFMAN PowerGlide padlocking handles and a foam-in-place gasket combine convenience with security. They are well-suited for use in petrochemical plants; pulp and paper processing; water treatment facilities; and food, pharmaceutical and packaging applications.

INDUSTRY STANDARDS

UL 508A Listed; Type 3R, 4, 4X, 12; File No. E61997

cUL Listed per CSA C22.2 No 94; Type 3R, 4, 4X, 12; File No. E61997

NEMA Type 3, 3R, 4, 4X, 12, 13

IEC 60529, IP66

Meets NEMA Type 3RX requirements

CERTIFICATIONS



FEATURES

Backs are 10 or 12 gauge stainless steel with x-form stiffeners

Seams continuously welded and ground smooth; no holes or knockouts

Removable centerpost for easy panel installation

Collar studs provided for mounting optional panels

Panel supports included

Heavy-duty lifting eyes are Type 316L stainless steel

Heavy-duty 3-point latching mechanism operated by Type 316L stainless steel PowerGlide padlocking handles

Body flange trough collar excludes liquids and contaminants

Heavy-duty stainless steel continuous hinges support each door

Bonding provision on doors; grounding studs on body

Accessory mounting channel provided in enclosure top

Data pocket is high-impact thermoplastic

12-in. (305-mm) removable floor stands are bolted to enclosure

Seamless foam-in-place one-piece gasket provides oil-tight and dust-tight seal against contaminants

External hardware manufactured of Type 316 stainless steel

PRODUCT ATTRIBUTES

Article Number: 26217

Height (H): 62.06in

Width (W): 60.06in

Depth (D): 18.06in

Material: Stainless Steel 316L

Finish: Brushed #4


Thickness (T): 12ga

Weight: 538lb

ADDITIONAL PRODUCT DETAILS

Purchase panels separately.

DIAGRAMS

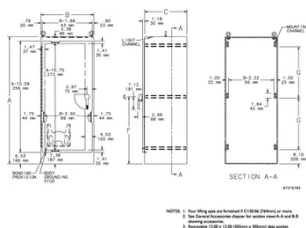

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE