

# Flat and Dome Screw Cover Contoured Type 4, 5.75x4.00x3.75, Gray, Steel

## CATALOG NUMBER

**A645DSC**



An economical solution for a broad range of electrical and terminal wiring applications that don't require a back panel, this enclosure features aesthetic, rounded corners and is available in flat and dome cover models for mounting flexibility.

## INDUSTRY STANDARDS

UL 508A Listed; Type 4, 6, 12, 13; File No. E61997

cUL Listed per CSA C22.2 No. 94; Type 4, 6, 12, 13; File No. E61997

NEMA Type 4, 6, 12, and 13

CSA, File No. 42186: Type 4, 12, and 13

IEC 60529, IP67

## FEATURES

Drawn enclosure

No welded seams or sharp corners

Cover screws

Formed flanged cover

Oil-resistant gasket

External welded-on mounting brackets for easy installation

Bonding provision on cover

Grounding stud on body

## PRODUCT ATTRIBUTES

Article Number: 57370

Height (H): 5.75in

Width (W): 4in

Depth (D): 4.75in

Material: Mild Steel

Finish: Powder Coated

Color: Gray

Color Code: ANSI 61

Thickness (T): 16ga

Cover Style: Dome

Interior Volume: 76.9in<sup>3</sup>

Mounting (G): 6.25in

Weight: 2.3lb


## ADDITIONAL PRODUCT DETAILS

---

Domed-cover enclosure depth = V + 1 in. (25 mm)

## DIAGRAMS

---

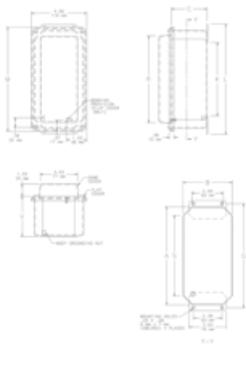

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**