

# Free-Stand Disconnect Enclosure Type 1, 72.00x73.00x18.00, Gray, Steel

## CATALOG NUMBER

**A72XN7318FSLP**



Free-Stand Disconnect Enclosures, Type 1, are an economical way to protect electrical and electronic equipment in applications that do not require extensive environmental protection.

## INDUSTRY STANDARDS

UL508A Listed; Type 1; File No. E61997

cUL Listed per CSA C22.2 No. 14; Type 1; File No. E61997

NEMA/EEMAC Type 1

IEC 60529 IP30

## FEATURES

4-in. high 10 gauge steel integral lifting base

Modified preferred disconnect cutout

Heights from 60 in. to 84 in. Usable height inside cabinet 4 in. less than nominal height.

Sturdy 7 gauge lifting tabs

Flush doors

3-point latch with heavy-duty handle

Screwdriver defeater in handle on primary door

Padlock provision in handle

Predrilled holes in lifting base provide bolt-down capability

Bonding provision on each door

Studs included for mounting optional panels on threaded bolts

Optional rack angles mount to top and bottom of front flanges

## PRODUCT ATTRIBUTES

Article Number: 13904

Height (H): 72in

Width (W): 73in

Depth (D): 18in

Material: Mild Steel

Finish: Powder Coated

Color: Light Gray

Color Code: RAL 7035

Thickness (T): 14ga

Weight: 479lb

## ADDITIONAL PRODUCT DETAILS


---

Purchase panels separately.

Catalog weights and dimensions are careful estimates but not guaranteed.

## DIAGRAMS

---

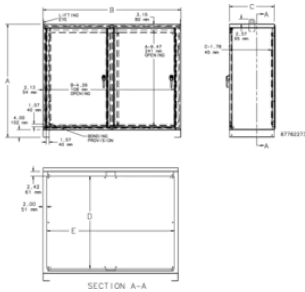

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**