


# Consolet Enclosure Type 12, 8.00x20.00x7.09, Gray ANSI 61, Mild Steel

## CATALOG NUMBER

**C8C20**

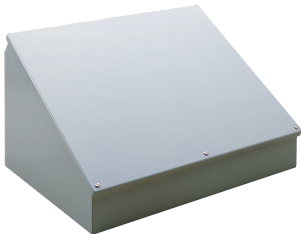

Consolets are ideal for mounting small control or instrumentation devices where the desirable access requires a 30- or 60-degree surface. These enclosures can be mounted on either of two sides for placement on desktops, pedestals or other flat surfaces to achieve maximum flexibility.

## INDUSTRY STANDARDS

UL 508A Listed; Type 12, 13; File No. E61997

cUL Listed per CSA C22.2 No. 94; Type 12, 13; File No. E61997

NEMA/EEMAC Type 12, 13

IEC 60529, IP65

## FEATURES

Can be positioned on either of two sides to provide a 30- or 60-degree surface access

Seams continuously welded and ground smooth

No holes or knockouts

Captivated cover screws thread into sealed wells

Bonding provision on cover

Oil-resistant gasket and adhesive

Continuous hinge

Pre-installed weld nuts for fast panel attachment

## PRODUCT ATTRIBUTES

Article Number: 59510

Height: 8in

Width: 20in

Depth: 7.09in

Material: Mild Steel

Finish: Powder Coated

Color: Gray

Color Code: ANSI 61

Thickness: 14ga

Weight: 14.9lb

## **WARNING**

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**