

# Mounting Bracket Kit, 3.06x1.34x.60, Polished, Stainless Steel 304

## CATALOG NUMBER

### CMFKSS



Mounting bracket kits are field-installable. DMFK1 and DMFK2 include two 14-gauge steel external mounting brackets and fasteners. CMFK, CMFKSS, and CMTGFT include four brackets per kit.

## FEATURES

Plastic mounting foot kits are rated for 500 lb (227 kg) maximum load

Sealing washers are provided with each kit to maintain Type 4 and 12 after installation

Stainless steel and plastic mounting bracket kits are rated to Type 4X

All hardware is included

## PRODUCT ATTRIBUTES

Article Number: 65750

Height (H): 3.06in

Width (W): 1.34in

Depth (D): 0.6in

Material: Stainless Steel 304

Finish: Polished

Thickness (T): 12ga


Fastener Thread Size: #3/8-16

L: 1.34in

Weight: 0.84lb

## DIAGRAMS

---

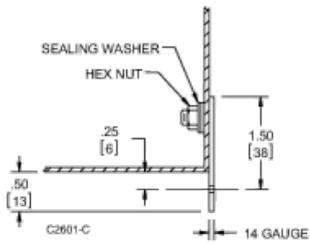

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**