


CableTek Horizontal Cable Manager 2U Double Sided, fits 19in, Black, Composite

CATALOG NUMBER

DCHD2

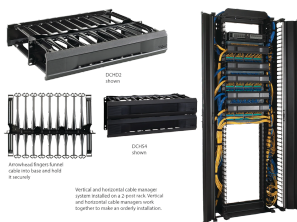

The CableTek Horizontal Cable Manager features heavy-duty endposts, arrowhead fingers and tool-less mounting to easily route Cat 5e, 6 and 6A cable horizontally in standard 19-in. cabinets or on 2- or 4-post open frame racks.

INDUSTRY STANDARDS

EIA 310-D

FEATURES

- Snap-in mounting provision holds cable manager in place while mounting screws are installed
- Robust arrowhead fingers are shaped to funnel cables into base and are made of black composite material
- Robust rounded end posts support cable as it enters and leaves cable manager and maintains proper cable bend radius
- Deep cable compartments allow maximum cable density
- Rounded edges throughout protect cable jackets from damage
- Pass-through holes on double-sided models protect cable while facilitating routing between front and back sides
- Single- and double-sided units provide high cable capacity, including 5e, 6 and 6A cables
- 1 RU and 2 RU heights allow greater flexibility in optimizing rack capacity
- Removable hinged cover opens top or bottom, snaps closed for assured cable protection and professional appearance
- Double-sided model has covers on both front and back
- Covers stay open during installation and maintenance procedures
- Horizontal and vertical cable managers designed as a system for streamlined appearance and improved functionality
- Combination head 10-32 and 12-24 screws included for mounting
- Made of UL listed black composite material

PRODUCT ATTRIBUTES

Article Number: 17243

Material: ABS

Finish: Smooth Matte

Color: Jet Black

Color Code: RAL 9005

Back Cross-Section Area: 14.1in²

Fill Rate, Back Cable, Cat 5e 0.22 in: 223

Fill Rate, Back Cable, Cat 6 0.25 in: 172

Fill Rate, Back Cable, Cat 6A 0.30 in: 119

Rack Units: 2U

Front Cross-Section Area: 13.2in²

Fill Rate, Front Cable, Cat 5e 0.22 in: 208

Fill Rate, Front Cable, Cat 6 0.25 in: 161

Fill Rate, Front Cable, Cat 6A 0.30 in: 112

Weight: 4lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE