


Gland Plate, Type 12, 16 Gauge, fits 17.00x5.00, Gray, Steel

CATALOG NUMBER

DLGP618

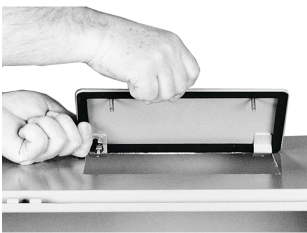

Gland plate, Type 12, 16 Gauge provides a removable cable egress and entry plate while maintaining enclosure rating of UL Type 12. Easily installed by cutting a rectangular opening in the enclosure and tightening the wing nuts.

FEATURES

Maintains UL/NEMA Type 12 if properly installed in an nVent HOFFMAN enclosure

PRODUCT ATTRIBUTES

Article Number: 37260

Material: Mild Steel

Finish: Powder Coated

Color: Gray

Color Code: ANSI 61

Thickness: 16ga

Weight: 2.9lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE