


Ultrx WiFi Type 4X, 608x595x321mm, Lt Gray, Fiberglass

CATALOG NUMBER

DU606030P

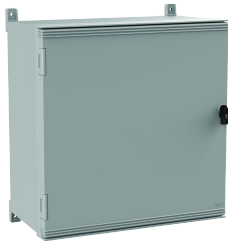

Ideal for locations such as tunnels, floor vaults, marinas, outside walls or rooftops, the lightweight Ultrx fiberglass WiFi cabinet does not impede WiFi or WLAN signals and has optional rack angles that can be added to support 19-inch rack-mount equipment.

INDUSTRY STANDARDS

UL 508A Listed; Type 4, 4X, 12, 13; File No. E61997

cUL Listed per CSA C22.2 No 94; Type 4, 4X, 12, 13; File No. E61997

Enclosure flammability rating per UL 508

Window flammability rating per UL 508

NEMA/EMAC Type 4, 4X, 12, 13

IEC 60529, IP66

Cabinets with solid doors are plenum rated.

FEATURES

Fiberglass is easily punched, drilled, filed or sawed

Seamless foam-in-place gasket assures watertight and dusttight seal

Enclosure may be rotated 180 degrees for left and right hinging

Molded-in drip shields are standard with each enclosure

Door opens 180 degrees

Replaceable breakaway hinges

Keylocking handle standard

Molded-in DIN bosses

Molded bosses on door provide additional mounting provisions

Integral mounting rails provide infinite panel adjustment front to back

Optional data pocket is high-impact thermoplastic

Enclosure and door made of molded fiberglass polyester that resists chemicals and temperature change

Impact-resistant polycarbonate window is permanently bonded in place

Fiberglass mounting brackets and stainless steel attachment screws are provided with each enclosure

Includes a 3/4-inch plywood panel for mounting equipment

PRODUCT ATTRIBUTES

Article Number: 14957
Height: 23.94in
Width: 23.43in
Depth: 12.64in
Material: Fiberglass
Finish: Smooth Matte
Color: Light Gray
Color Code: RAL 7035
Thickness: 0.15in
Window Size: 19.62 x 19.12in
Mounting: 21.86 x 22.36in
Door Type: Solid
Internal Dimensions: 23.94 x 23.44 x 12.64in
Weight: 44lb

ADDITIONAL PRODUCT DETAILS

Wood panel included with enclosure, optional steel panels must be ordered separately

Window size applies to window door cabinets only

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE