


Panel 19-inch Bottom-Hinged 4U, 203x508x305mm, Black, Steel

CATALOG NUMBER

E19BHPM4U12

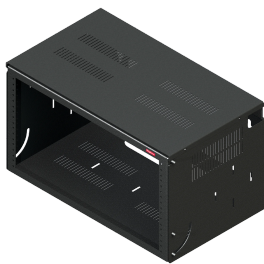

Hinged panel pivots to 90 degrees with positive stop, providing a stable platform for punch-down interconnects. Thumbscrews secure the panel in the upright position. Integral Velcro® cable tiedown slots facilitate cable routing. Cover protects equipment and cables. Shipped fully assembled. Velcro® is a trademark of Velcro Industries B.V.

INDUSTRY STANDARDS

UL 2416 Listed; File No. E230874

cUL CSA C22.2 No. 182.4 Listed, File No. E230874

EIA 310-D

FEATURES

Hinged panel pivots to 90 degrees with positive stop, providing a stable platform for punch-down interconnects

Thumbscrews secure the panel in the upright position

Integral Velcro® cable tiedown slots facilitate cable routing

Cover protects equipment and cables

Shipped fully assembled

PRODUCT ATTRIBUTES

Article Number: 11007

Height: 8in

Width: 20in

Depth: 12in

Material: Mild Steel

Finish: Powder Coated

Color: Jet Black

Color Code: RAL 9005

Body Thickness: 16ga

Door Thickness: 12ga

Rack Units: 4U

Load Rating: 25lb

Weight: 19.76lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE