


# Extra-Large Pushbutton Enclosures Type 12, 36PBx22.5mm, Gray, Steel

## CATALOG NUMBER

**E36PBY25M**

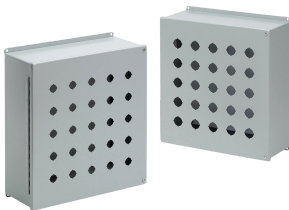

Extra-Large Pushbutton Enclosures with Panels are designed to hold 30.5-mm and 22.5-mm pushbuttons and switches, with 2.50-in. (64-mm) center-to-center of pushbutton holes.

## INDUSTRY STANDARDS

UL 508A Listed; Type 12, 13; File No. E61997

cUL Listed per CSA C22.2 No. 94; Type 12, 13; File No. E61997

NEMA/EEMAC Type 12, 13

CSA File Number 42186: Type 12

IEC 60529, IP65

## FEATURES

Seams continuously welded and ground smooth

Captivated cover screws thread into sealed wells

Continuous hinge

Factory stamped 4-way pushbutton holes

Oil-resistant gasket

Removable 14 gauge panel included, supported by weldnuts

Bonding provision on cover

External welded-on mounting brackets for easy installation

30.5-mm or 22.5-mm size holes

## PRODUCT ATTRIBUTES

Article Number: 13062

Height: 18.5in

Width: 17.5in

Depth: 6in

Material: Mild Steel

Finish: Powder Coated

Color: Gray

Color Code: ANSI 61

Thickness: 14ga

Hole Size: 0.88in

Hole Quantity: 36

Mounting: 19.00 x 16.62in

Weight: 31.1lb

## **WARNING**

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**