

# ComLine OSP Package Type 4X, 600x600x500mm, Lt Gray, Aluminum

## CATALOG NUMBER

**ECL606050P**



A complete, off-the-shelf package for 19-inch rack equipment, lightweight ComLine OSP Wall-Mount Cabinets are constructed of corrosion-resistant aluminum with a foam-in-place gasket that secures and protects sensitive equipment in outdoor applications. Available with or without back-up battery compartment.

## INDUSTRY STANDARDS

UL 508A Listed; Type 3, 3R, 4, 4X, 12; File No. E61997

CSA: Type 3, 3R, 4, 4X, 12

NEMA/EEMAC Type 3, 3R, 4, 4X, 12

EC60529, IP66

Designed to meet Telcordia NEBS™ GR-487, GR-63 and IEC 48D

EIA 310-D with 19 in. spacing for rack equipment

Meets BICSI TDMM, Tenth Edition, Chapter 7, Telecommunication Enclosures (TE)

Cabinet is RoHS compliant

NEBS is a trademark of Telcordia

## FEATURES

Solar shield helps keep enclosure interior cool when cabinet is installed outdoors and directs liquids away from cabinet opening; can be removed for indoor installations

Foam-in-place gasket provides environmental seal

Padlocking L-Handle provides a tight, secure door seal

Doorstop holds door in place during service for easier and faster maintenance

Heavy-duty hinged door is easily removed to facilitate equipment installation and removal; maximum door load 50 lb. (22.7 kg)

Rack angles adjustable front-to-rear of cabinet

Gland plates available with cutouts that fit HOFFMAN T15, T20 and CR23 air conditioners and HOFFMAN XR20 and XR29 heat exchangers (Indoor use only)

Radius corners on cabinet eliminate sharp edges

Stainless steel fasteners resist corrosion to maintain professional appearance

Pole mounting kits available for all sizes

Pad mounting plinth available for 600mm deep cabinets

Battery compartment has front vented captivated door

Rack angles have EIA universal standard square hole spacing

Body includes studs for ground bar and rear mounting studs for wood panel

## PRODUCT ATTRIBUTES

Article Number: 17026

Height (H): 23.62in

Width (W): 23.62in

Depth (D): 19.68in

Material: Aluminum

Finish: Powder Coated

Color: Light Gray

Color Code: RAL 7035

Body Thickness: 0.125in

Door Thickness: 0.1in

Rack Units: 12U


Weight: 75lb

## ADDITIONAL PRODUCT DETAILS

Note – SR20 and SR2 are for indoor use only

## DIAGRAMS

COMLINE OSP Package Without Battery Compartment

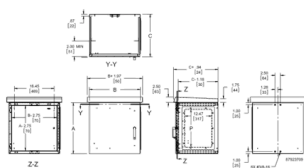

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**