


Elbow 90-Degree Lay-in Inside Opening, fits 10.00x10.00, Galvanized, Steel

CATALOG NUMBER

F101090EINGV

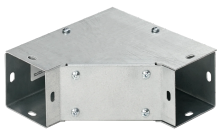

Lay-in Galvanized 90-Degree Elbow with Inside Opening are used for continuous run with 90-degree turns. Top and inside covers removable. Lay-in feature allows wires and cables can be laid in along wireway run. No pulling through of wires or cables prevents damage to insulation that often occurs in a pull-through wiring system.

FEATURES

Lay-in Galvanized 90-Degree Elbow with Inside Opening are used for continuous run with 90-degree turns

Top and inside covers removable

Lay-in feature allows wires and cables can be laid in along wireway run

No pulling through of wires or cables prevents damage to insulation that often occurs in a pull-through wiring system

PRODUCT ATTRIBUTES

Article Number: 13147

Type: Elbow

Height: 10in

Width: 10in

Material: Mild Steel

Finish: Galvanized

Thickness: 14ga

Weight: 15.9lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE