

Elbow 90-Degree LayIn Wireway Inside Opening, 2.50x2.50, Gray, Mild Steel

CATALOG NUMBER

F22LE9B



Lay-in Hinged-Cover 90-Degree Elbows are used for right-angle wireway installations. Because sections of lay-in wireway can be mounted with covers oriented in any direction, three different 90-degree elbows are available. Proper selection allows the user to maintain the same access and thereby preserve the lay-in feature for right-angle installations.

INDUSTRY STANDARDS

Certified by Canadian Standards Association

FEATURES

Lay-in Hinged-Cover 90-Degree Elbows are used for right-angle wireway installations

Because sections of lay-in wireway can be mounted with covers oriented in any direction, three different 90-degree elbows are available

Proper selection allows the user to maintain the same access and thereby preserve the lay-in feature for right-angle installations

PRODUCT ATTRIBUTES

Article Number: 18120

Type: Elbow

Height (H): 2.5in

Width (W): 2.5in

Material: Mild Steel

Finish: Galvanized; Powder Coated

Color: Gray


Color Code: ANSI 61

Thickness (T): 14ga

Sealing Plate Type: Flat

Sealing Plate Quantity: 1

DIAGRAMS

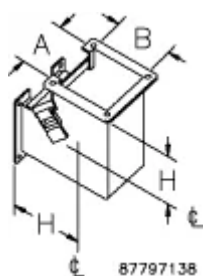

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE