

Elbow 45-Degree Outside Opening, 2.50x2.50, Gray, Steel

CATALOG NUMBER

F22LE45C



Lay-in Hinged-Cover 45-Degree Elbows are used for continuous wireway runs with 45-degree turns. Because sections of lay-in wireway can be mounted with covers oriented in any direction, three different 45-degree elbows are available. Proper selection allows the user to maintain the same access and thereby preserve the lay-in feature for right-angle installations.

INDUSTRY STANDARDS

Certified by Canadian Standards Association.

FEATURES

Lay-in Hinged-Cover 45-Degree Elbows are used for continuous wireway runs with 45-degree turns

Because sections of lay-in wireway can be mounted with covers oriented in any direction, three different 45-degree elbows are available

Proper selection allows the user to maintain the same access and thereby preserve the lay-in feature for right-angle installations

PRODUCT ATTRIBUTES

Article Number: 18160

Type: Elbow

Height (H): 2.5in

Width (W): 2.5in

Material: Mild Steel

Finish: Galvanized; Powder Coated

Color: Gray

Color Code: ANSI 61

Thickness (T): 14ga

Sealing Plate Type: Flat


Sealing Plate Quantity: 1

Weight: 2.1lb

ADDITIONAL PRODUCT DETAILS

Each sealing plate also includes one gasket and one set of screws to join sections.

DIAGRAMS

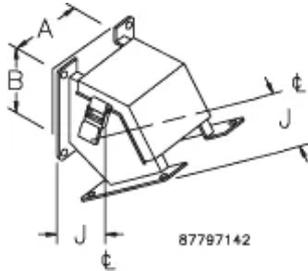

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE