


Cutoff Fitting Lay-in, 2.50x2.50, Gray, Steel

CATALOG NUMBER

F22LXL

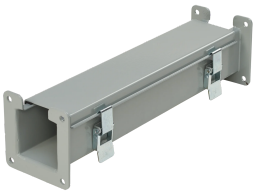

Lay-In Hinged Cover Cutoff Fittings are used for lengths of 9.00 inch (229 mm) to 15.00 inch (381 mm). Body comes in two pieces. Shorten body and cover to the desired length and weld together. Fittings are finished with paint over plated surfaces.

FEATURES

Lay-In Hinged Cover Cutoff Fittings are used for lengths of 9.00 inch (229 mm) to 15.00 inch (381 mm)

Body comes in two pieces. Shorten body and cover to the desired length and weld together

Fittings are finished with paint over plated surfaces

PRODUCT ATTRIBUTES

Article Number: 18090

Type: Cut-Off Fitting

Height: 2.5in

Width: 2.5in

Material: Mild Steel

Finish: Galvanized; Powder Coated

Color: Gray

Color Code: ANSI 61

Thickness: 14ga

Sealing Plate Type: Flat

Sealing Plate Quantity: 1

Weight: 5.2lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE