


Sealing Plate 90-Degree Angle Lay-in HC Type 12 and 3R, 2.50x2.50, Gray, Steel

CATALOG NUMBER

F22LSAG

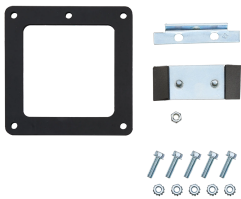

Lay-in Hinged-Cover 90-Degree Angle Sealing Plates are used for junction to a lay-in wireway section or fitting to a closure plate, a box connector, a non-lay-in cut-off fitting or any similar non-lay-in section or fitting. Each sealing plate also includes one gasket and one set of screws to join sections.

FEATURES

Lay-in Hinged-Cover 90-Degree Angle Sealing Plates are used for junction to a lay-in wireway section or fitting to a closure plate, a box connector, a non-lay-in cut-off fitting or any similar non-lay-in section or fitting

Each sealing plate also includes one gasket and one set of screws to join sections

PRODUCT ATTRIBUTES

Article Number: 18230

Type: Sealing Plate

Height: 2.5in

Width: 2.5in

Material: Mild Steel

Finish: Galvanized; Powder Coated

Color: Gray

Color Code: ANSI 61

Thickness: 14ga

Weight: 0.4lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE