

# Transposition Sections CCW, 4.00x4.00, Gray, Steel

## CATALOG NUMBER

---

### F44LKOKT



Lay-in Hinged-Cover Transposition Sections are used when it is necessary to rotate the open side of the wireway run by 90 degrees and still retain the lay-in feature.

## INDUSTRY STANDARDS

---

Certified by Canadian Standards Association.

## FEATURES

---

Lay-in Hinged-Cover Transposition Sections are used when it is necessary to rotate the open side of the wireway run by 90 degrees and still retain the lay-in feature

## PRODUCT ATTRIBUTES

---

Article Number: 19820

Type: Transposition Section

Height (H): 4in

Width (W): 4in

Material: Mild Steel

Finish: Galvanized; Powder Coated

Color: Gray

Color Code: ANSI 61

Thickness (T): 14ga

Sealing Plate Quantity: 1

Sealing Plate Type: Flat

Weight: 6.4lb

## ADDITIONAL PRODUCT DETAILS


---

Each sealing plate also includes one gasket and one set of screws to join sections.

Certified by Canadian Standards Association.

## DIAGRAMS

---

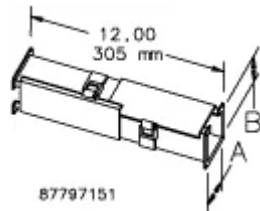

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**