

InLine Hinged Cover 1/4 Turn Latch Type 4X, 150x150x120mm, Brushed, Stainless 316

CATALOG NUMBER

LHC151512SS6



Aesthetic styling, flush latches and an attractive, stroked finish make InLine Enclosures an excellent choice when style and functionality are important. InLine Enclosures have an outward formed body flange to prevent contaminants from entering the enclosure and are available in three cover styles: hinged window door, hinged solid door and solid screw cover.

INDUSTRY STANDARDS

UL 508A Listed; Type 4, 4X, 12; File No. E61997

Mounting brackets required to meet UL external mounting requirements.

NEMA/EEMAC Type 4, 4X, 12

IEC 60529, IP66

FEATURES

Seams continuously welded and ground smooth

External formed body flange trough

Large perimeter body opening

Fastening holes in back of body for direct mounting or optional external mounting brackets

Seamless foam-in-place gasket

M6 bonding provision on cover, M6 ground stud in body

Furnished hardware kit includes panel mounting screws, grounding hardware and sealing washers for wall-mounting holes

PRODUCT ATTRIBUTES

Article Number: 87740

Height (H): 5.91in

Width (W): 5.91in

Depth (D): 4.72in

Material: Stainless Steel 316L

Finish: Brushed #4

Body Thickness: 14ga

Door Thickness: 16ga


Mounting (G x H): 5.18 x 3.36in

Weight: 3.96lb

ADDITIONAL PRODUCT DETAILS

Purchase panels separately.

DIAGRAMS

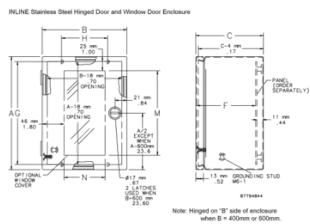

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE