

InLine Landscape Enclosure Type 4 12, 230x770x155mm, Light Gray, Mild Steel

CATALOG NUMBER

LHC237716



When applications require mounting electrical components the full width of an enclosure, the landscape orientation of this aesthetic InLine Enclosure makes it possible. Full-width mounting brackets can be drilled anywhere along their length, providing maximum mounting flexibility.

INDUSTRY STANDARDS

Solid Door Enclosures:

UL 508A Listed; Type 3, 4, 12; File No. E61997

cUL Listed per CSA C22.2 No. 94; Type 3, 4, 12; File No. E61997

NEMA/EEMAC Type 3, 4, 12

IEC 60529, IP66

Window Door Enclosures:

UL 508A Listed; Type 3, 4, 12; File No. E61997

NEMA/EEMAC Type 3, 4, 12

IEC 60529, IP66

FEATURES

Metric dimensions

Seams continuously welded and ground smooth

External formed body flange channels away liquids

Large perimeter body opening

External welded-on mounting brackets for easy installation

Bonding provision on cover and door

Hardware kit includes panel mounting screws and grounding hardware

Removable hinged door

Self-grounding, slotted quarter-turn latches

Door opens 180 degrees


Window door models include flush-mounted 4.8-mm (3/16-in.) clear polycarbonate window

Seamless foam-in-place gasket

PRODUCT ATTRIBUTES

Article Number: 11027
Height (H): 9.06in
Width (W): 30.31in
Depth (D): 6.1in
Material: Mild Steel
Finish: Powder Coated
Color: Light Gray
Color Code: RAL 7035
Thickness (T): 16ga
Mounting Studs (J): 28.57in
Clear Space Above Panel: 5.51in
Cover Style: Solid
Weight: 21.6lb

DIAGRAMS

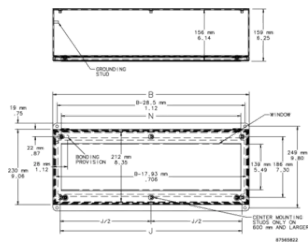

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE