

# InLine Hinged Cover 1/4-Turn Latch Type 4X, 350x300x200mm, Brushed, Stainless 304

## CATALOG NUMBER

**LHC353020SS**



Aesthetic styling, flush latches and an attractive, stroked finish make InLine Enclosures an excellent choice when style and functionality are important. InLine Enclosures have an outward formed body flange to prevent contaminants from entering the enclosure and are available in three cover styles: hinged window door, hinged solid door and solid screw cover.

## INDUSTRY STANDARDS

UL 508A Listed; Type 4, 4X, 12; File No. E61997

Mounting brackets required to meet UL external mounting requirements.

NEMA/EEMAC Type 4, 4X, 12

IEC 60529, IP66

## FEATURES

Seams continuously welded and ground smooth

External formed body flange trough

Large perimeter body opening

Fastening holes in back of body for direct mounting or optional external mounting brackets

Seamless foam-in-place gasket

M6 bonding provision on cover, M6 ground stud in body

Furnished hardware kit includes panel mounting screws, grounding hardware and sealing washers for wall-mounting holes

## PRODUCT ATTRIBUTES

Article Number: 61850

Height (H): 13.78in

Width (W): 11.81in

Depth (D): 7.87in

Material: Stainless Steel 304

Finish: Brushed #4

Body Thickness: 14ga

Door Thickness: 16ga


Mounting (G x H): 13.05 x 9.27in

Weight: 16lb

## ADDITIONAL PRODUCT DETAILS

Purchase panels separately.

## DIAGRAMS

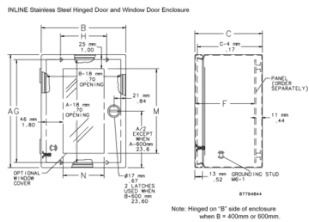

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**