

InLine Enclosure Screw Cover Type 4X, 250x200x150mm, Brushed, Stainless 316

CATALOG NUMBER

LSC252015SS6



Aesthetic styling, flush latches and an attractive, stroked finish make InLine Enclosures an excellent choice when style and functionality are important. InLine Enclosures have an outward formed body flange to prevent contaminants from entering the enclosure and are available in three cover styles: hinged window door, hinged solid door and solid screw cover.

INDUSTRY STANDARDS

UL 508A Listed; Type 4, 4X, 12; File No. E61997

Mounting brackets required to meet UL external mounting requirements.

NEMA/EEMAC Type 4, 4X, 12

IEC 60529, IP66

FEATURES

Seams continuously welded and ground smooth

External formed body flange trough

Large perimeter body opening

Fastening holes in back of body for direct mounting or optional external mounting brackets

Seamless foam-in-place gasket

M6 bonding provision on cover, M6 ground stud in body

Furnished hardware kit includes panel mounting screws, grounding hardware and sealing washers for wall-mounting holes

PRODUCT ATTRIBUTES

Article Number: 83860

Height (H): 9.84in

Width (W): 7.87in

Depth (D): 5.91in


Material: Stainless Steel 316L

Finish: Brushed #4

Door Thickness: 16ga

Weight: 5lb

Purchase panels separately.

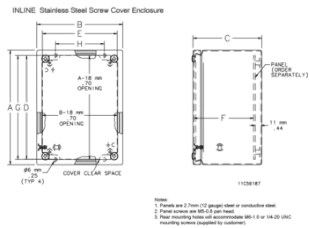

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE