

InLine Hinged Window Cover Type 4X, 250x200x150mm, Brushed, Stainless 304

CATALOG NUMBER

LWC252015SS



Aesthetic styling, flush latches and an attractive, stroked finish make InLine Enclosures an excellent choice when style and functionality are important. InLine Enclosures have an outward formed body flange to prevent contaminants from entering the enclosure and are available in three cover styles: hinged window door, hinged solid door and solid screw cover.

INDUSTRY STANDARDS

UL 508A Listed; Type 4, 4X, 12; File No. E61997

Mounting brackets required to meet UL external mounting requirements.

NEMA/EEMAC Type 4, 4X, 12

IEC 60529, IP66

FEATURES

Seams continuously welded and ground smooth

External formed body flange trough

Large perimeter body opening

Fastening holes in back of body for direct mounting or optional external mounting brackets

Seamless foam-in-place gasket

M6 bonding provision on cover, M6 ground stud in body

Furnished hardware kit includes panel mounting screws, grounding hardware and sealing washers for wall-mounting holes

PRODUCT ATTRIBUTES

Article Number: 61870

Height (H): 9.84in

Width (W): 7.87in

Depth (D): 5.91in

Material: Stainless Steel 304

Finish: Brushed #4

Body Thickness: 14ga

Door Thickness: 16ga

Window Size (M x N): 7.83 x 4.53in


Mounting (G x H): 9.12 x 5.33in

Weight: 7.4lb

ADDITIONAL PRODUCT DETAILS

Purchase panels separately.

DIAGRAMS

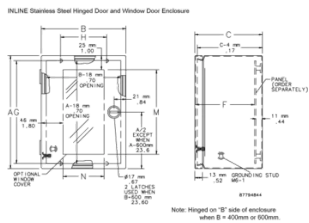

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE