




We connect and protect

ProLine G2 100-mm Plinth Bases, fits 800x400mm, Black, Steel

Catalog Number

P2BP184

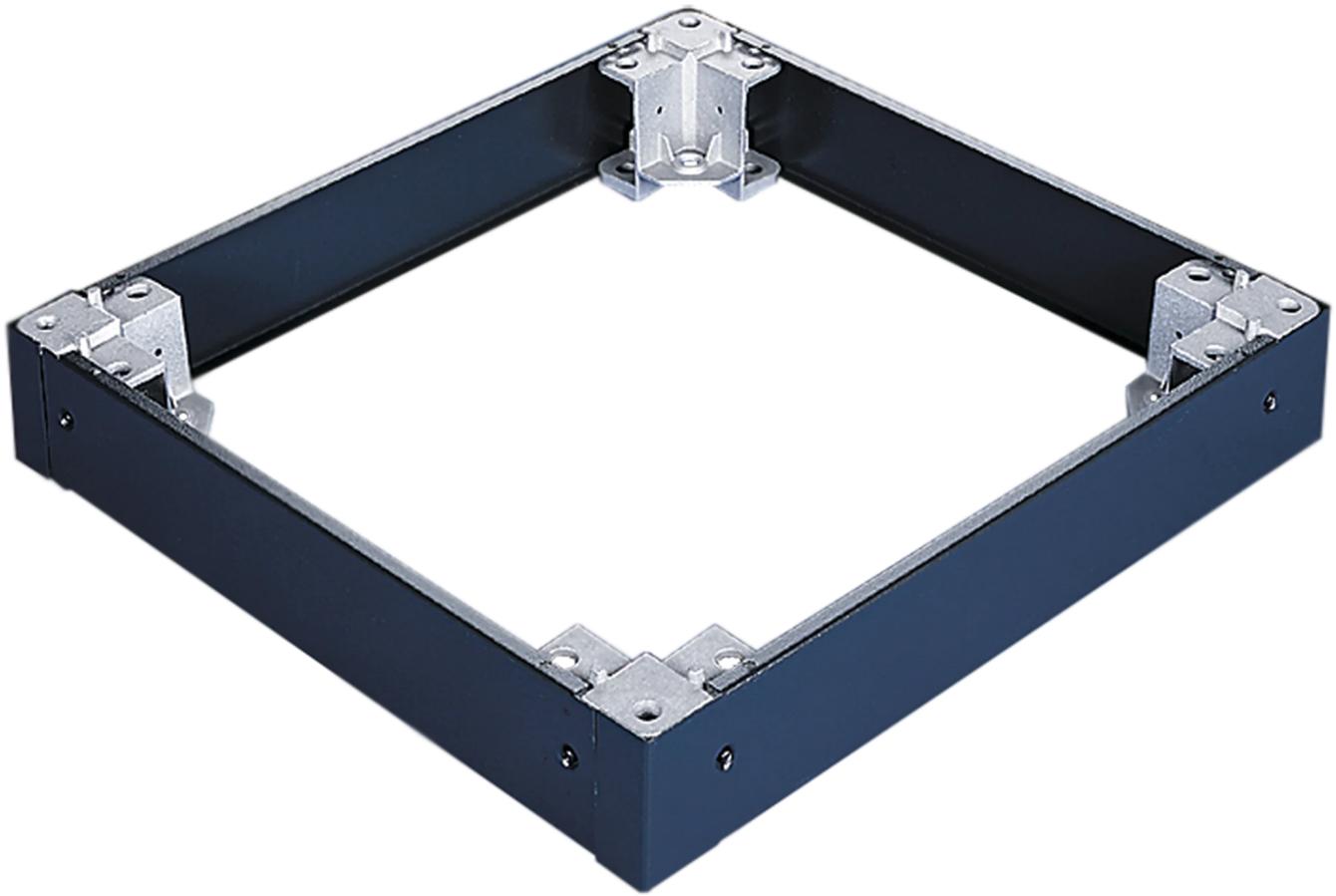

- ProLine G2 Plinth Bases install under an enclosure to provide space for cables to enter from below.

Features

- Four access panels for cable management options at the base of the enclosure
- Sturdy cast aluminum corner supports for superior performance under load

- Corner blocks can be installed onto the base of the frame independent of the cover plates, enabling the cover plates to be attached after integration and just prior to shipment
- Stackable up to 400mm in height using Plinth Base Stacking Kit (not included)
- 100 mm or 200 mm options
- To maintain a NEMA Type 12 environmental rating, gland plate must also be used in the base of the enclosure
- Installation hardware included

PRODUCT ATTRIBUTES

- Article Number: 31096
- Height: 3.94in
- Width: 31.46in
- Depth: 14.33in
- Material: Mild Steel
- Finish: Powder Coated
- Color: Jet Black
- Color Code: RAL 9005
- Thickness: 16ga
- Weight: 13lb

Warning

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



nVent

Our powerful portfolio of brands:

- Caddy
- Erico
- Hoffman
- IlSCO
- Schroff
- Trachte

©2026 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice. This document is system-generated.

[nVent.com/HOFFMAN](https://www.nVent.com/HOFFMAN) |