


PROLINE-PC 20-Degree Control Compartment

PC/SY, fits 600mm, Brushed, SS304

CATALOG NUMBER

PC20A6SS

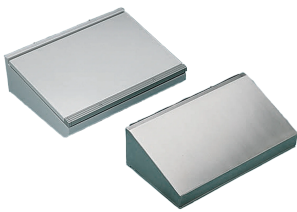

Reversible design provides 20-degree angled surface for mounting operator controls. Smaller angle maximizes mounting space available. Screw cover on the flat side allows easy access inside compartment. Screw cover has foam-in-place gasketing. Compartment is gasketed around the open rear surface to extend the UL and CSA rating to the control compartment interior. Ground stud and mounting hardware included.

FEATURES

Reversible design

Screw cover on the flat side has foam in place gasket

Ground stud and mounting hardware included.

PRODUCT ATTRIBUTES

Article Number: 35419

Height: 6.89in

Width: 23.3in

Depth: 12.75in

Material: Stainless Steel 304

Finish: Brushed

Thickness: 14ga

Weight: 21lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE