


Solid Door For ProLine Sloped Front, fits 407x600mm, Lt Gray, Steel

CATALOG NUMBER

PDS46F

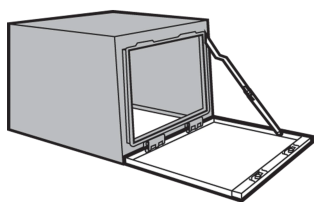

Solid doors are available with or without windows. Doors are hinged at lower edge and have quarter-turn latches. A stop arm assembly holds the door at 95 degrees (horizontal) from its closed position. Standard latch and insert options are available. Ground stud and mounting hardware are included. Seamless polyurethane foam-in-place gasket assures watertight and dust-tight seal. Window doors feature a maximum size .25-in.-thick polycarbonate window with a smoke-gray tint. Window is field-replaceable.

FEATURES

Doors are hinged at lower edge and have quarter-turn latches

Ground stud and mounting hardware

PRODUCT ATTRIBUTES

Article Number: 36639

Height: 15.75in

Width: 23.62in

Depth: 22.23in

Material: Mild Steel

Finish: Powder Coated

Color: Light Gray

Color Code: RAL 7035

Thickness: 16ga

Door Size: 15.91 x 23.30in

Weight: 10lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE