


# Window Door For ProLine Sloped Front, fits 407x600mm, Lt Gray, Steel

## CATALOG NUMBER

### PDW46F

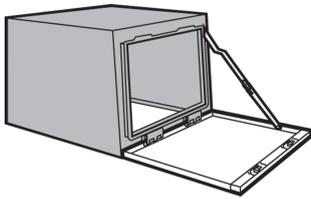

Solid doors are available with or without windows. Doors are hinged at lower edge and have quarter-turn latches. A stop arm assembly holds the door at 95 degrees (horizontal) from its closed position. Standard latch and insert options are available. Ground stud and mounting hardware are included. Seamless polyurethane foam-in-place gasket assures watertight and dust-tight seal. Window doors feature a maximum size .25-in.-thick polycarbonate window with a smoke-gray tint. Window is field-replaceable.

## FEATURES

Doors are hinged at lower edge and have quarter-turn latches

Ground stud and mounting hardware

## PRODUCT ATTRIBUTES

Article Number: 36709

Height: 15.75in

Width: 23.62in

Depth: 22.23in

Material: Mild Steel

Finish: Powder Coated

Color: Light Gray

Color Code: RAL 7035

Thickness: 16ga

Window Size: 10.00 x 17.00in

Door Size: 15.91 x 23.30in

Weight: 10.4lb

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**