

ProLine Gold Series 1-Bay Desk Console Type 12, 1176x808x469, Lt Gray, Steel

CATALOG NUMBER

PGLD1285DC



The ProLine Gold Series Desk Console provides an ideal surface for mounting HMI controls such as keyboards, switches, lights or dials, and it is ergonomically designed so operators can sit or stand while working. The console also provides a large space for mounting internal components and controls and can be configured in an arc by using the wedge accessory.

INDUSTRY STANDARDS

UL 508A Listed; Type 4, 12; File Number E61997

cUL Listed per CSA C22.2 No 94; Type 4, 12; File No. E61997

NEMA/EEMAC Type 4, 12

IEC 60529, IP55, IP66

FEATURES

25-degree sloped top

Seams continuously welded and ground smooth

Top door prop allows for single-handed operation

Built-in top door handle

Quarter-turn latches hold top door securely closed

ProLine latching system and keylocking swing handles on front doors and on rear doors of dual-access enclosures

Internal rails on dual-access enclosures facilitate mounting of ProLine internal components

Full access provides maximum mounting space and easy access to interior components

PRODUCT ATTRIBUTES

Article Number: 14388

Height (H): 46.28in

Width (W): 31.81in

Depth (D): 18.47in

Material: Mild Steel


Finish: Powder Coated

Color: Light Gray

Color Code: RAL 7035

Weight: 175lb

DIAGRAMS

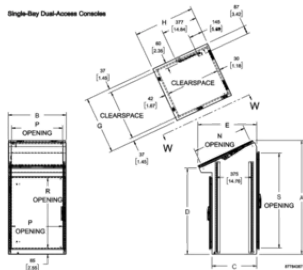

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE