


# Remote Door Switch for ProLine, 120/250VAC 10Amp, Galvanized, Steel

## CATALOG NUMBER

**PLFSWD**

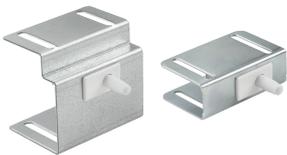

The Remote Door Switch can activate a light or other electrical component when the enclosure door is opened.

## INDUSTRY STANDARDS

UL508A Recognized, Type 3R, 4, 4X, 12; File E61997

cUL Recognized per CSA C22.2 No. 14-13; Type 3R, 4, 4X, 12; File E61997

## FEATURES

Mounts on enclosure frame and includes mounting hardware

Mounting plate is 14 gauge

## PRODUCT ATTRIBUTES

Article Number: 26949

Height: 1.26in

Width: 0.67in

Depth: 0.87in

Material: Mild Steel

Finish: Galvanized

Thickness: 14ga

Weight: 0.38lb

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**