

Partial Subpanel, 400x1200, fits 700H (min.), White, Steel

CATALOG NUMBER

PPP412



Partial Subpanels have flanges on four sides. Panels can be positioned vertically in 25-mm increments and also can be positioned at any depth in 25-mm increments using the optional grid straps. All necessary mounting hardware is included.

FEATURES

12 gauge steel; conductive or white painted finish

All necessary mounting hardware is included

Partial Subpanels have flanges on four sides for added strength.

Panels can be positioned vertically in 25-mm increments, but also can be positioned at any depth in 25-mm increments using depth-mounted grid straps for securing (sold separately)

PRODUCT ATTRIBUTES

Article Number: 99240

Material: Mild Steel


Weight: 25.58lb

Color: White

Finish: Powder Coated

Thickness (T): 12ga

DIAGRAMS

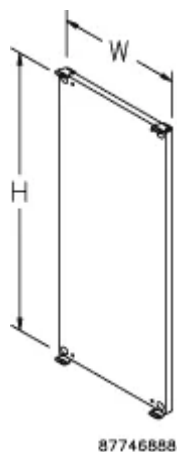

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE