


# Pagoda Tops, fits 1600x800mm, Painted

## CATALOG NUMBER

**PPT168**

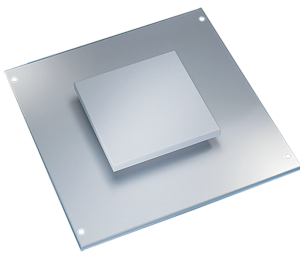

Pagoda Tops are available to fit on standard frames. Design features a drip-proof raised pagoda vent with a 115-volt integral axial exhaust fan. Double-bay Pagoda Tops have one drip-proof raised pagoda vent opening positioned over one bay that can be oriented for right or left ventilation.

## INDUSTRY STANDARDS

This component is rated UL Type 1. Installing this component on an enclosure brings the enclosure rating to UL Type 1.

## FEATURES

Bolts secure pagoda top to frame (lifting eyes can be used instead of bolts).

Drip-protected vent

## PRODUCT ATTRIBUTES

Article Number: 20449

Material: Mild Steel

Frame Type: Double-Bay

Weight: 49lb

Color: Light Gray

Color Code: RAL 7035

Finish: Powder Coated

Thickness: 14ga

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**