


QLine E EMC Enclosure Type 4X, 175x175x74mm, Light Gray, Polycarbonate

CATALOG NUMBER

Q18188PCEMC

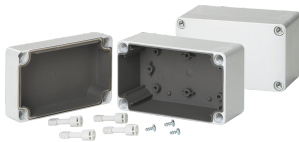

Medium-size QLine E polycarbonate EMC enclosures have contoured bodies and flush cover screws for an attractive, contemporary appearance while also providing EMC protection in corrosive environments.

INDUSTRY STANDARDS

UL 508A Listed; Type 4, 4X, 12, 13; File No. E61997

cUL Listed per CSA C22.2 No 94: Type 4, 4X, 12, 13; File No. E61997

Enclosure flammability evaluated per UL 508A

NEMA/EEMAC Type 4, 4X, 12, 13

IEC 60529, IP66

FEATURES

Body is impact-resistant polycarbonate

EMC conductive coating in base and cover

Gasket of silver/silicone

Mounting holes molded directly under cover screws

Screws provided for mounting optional panel

Polycarbonate material is easily punched, drilled, filed or sawed

Cross-point flush cover screws are strong, durable polyamide

Mounting tracks along body side walls for PC card installation

Molded internal pads for mounting optional panels, rails and other components

PRODUCT ATTRIBUTES

Article Number: 45729

Height: 6.89in

Width: 6.89in

Depth: 2.91in

Material: Polycarbonate

Finish: Smooth Matte

Color: Light Gray

Color Code: RAL 7035

Body Thickness: 0.12in

Door Thickness: 0.14in

Interior Finish: EMC Conductive Coating

Mounting: 6.30 x 6.30in

Internal Dimensions: 6.63 x 6.63 x 2.65in

Weight: 1.1lb

ADDITIONAL PRODUCT DETAILS

Purchase panels separately

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE