


Fan Shroud Kits Type 3R, fits 4-inch fan, Brushed, Stainless Steel 304

CATALOG NUMBER

T4S3RSS

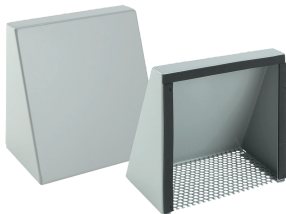

Fan Shroud Kit, Type 3R, protects enclosure openings from rain, sleet and snow. It comes with a gasket, ventilation screen, and is available in both painted mild steel and stainless steel.

INDUSTRY STANDARDS

UL 508A Listed; Type 3R; File No. E61997

cUL Listed per CSA C22.2 No 94; Type 3R; File No. E61997

Maintains UL/cUL Type 3R rating when properly installed on UL/cUL Type 3R enclosure.

NEMA/EEMAC Type 3R

IEC 60529, IP22

FEATURES

Two fan shrouds per package

Perforated ventilation screen

Pressure-sensitive adhesive-backed gasket and mounting hardware

PRODUCT ATTRIBUTES

Article Number: 14075

Height: 6in

Width: 6in

Depth: 4.69in

Material: Stainless Steel 304

Finish: Brushed #4

Thickness: 16ga

Dimensions: 6.00 x 6.00in

Weight: 3.9lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE