


TFP Exhaust Grille fits 6-inch Package, 7.77x8.83x1.25, Brushed, Stainless 304

CATALOG NUMBER

TEP6SS

Type 1 or Type 12 exhaust option for TFP Filter Fans

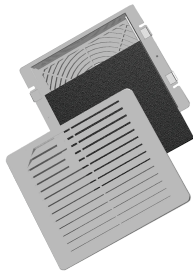

FEATURES

TFP Exhaust Grilles includes standard replacement filters that are washable foam (Type 1) or disposable (Type 12)

To maintain UL Type 12 rating on the enclosure, UL Type 12 filters must be used on the fan package inlet

PRODUCT ATTRIBUTES

Article Number: 11231

Height: 7.77in

Width: 8.83in

Depth: 1.25in

Material: Stainless Steel 304

Finish: Brushed

Weight: 0.9lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE