


Ultrx Rack Angles (Type RA), fits 775mm, Plated, Steel

CATALOG NUMBER

UURA7560

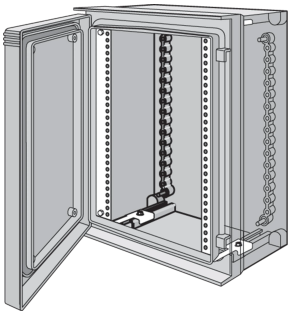

Pairs of full-length rack-mounting angles are available for mounting 1- inch (483-mm) rack-mounted equipment. Type RA angles have .281-inch (7-mm) diameter mounting holes, spaced per EIA standard RS-310-D (universal spacing). Use Clip Nut Package (AN1032) to provide tapped holes at desired locations. Angles and mounting hardware are plated steel. Mounting hardware is furnished.

CERTIFICATIONS



FEATURES

For use with Ultrx Series Products

Pairs of full-length rack-mounting angles are available for mounting 1- inch (483-mm) rack-mounted equipment.

Type RA angles have .281-inch (7-mm) diameter mounting holes, spaced per EIA standard RS-310-D (universal spacing). Use Clip Nut Package (AN1032) to provide tapped holes at desired locations.

Angles and mounting hardware are plated steel. Mounting hardware is furnished.

PRODUCT ATTRIBUTES

Article Number: 33860

Material: Mild Steel

Finish: Zinc Plated

Thickness: 14ga

Rack Units: 15U

Weight: 4.7lb

ADDITIONAL PRODUCT DETAILS

Use UURA6060 with DATACOM Ultrx Fiberglass Type 4X WiFi Cabinet.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE