



Straight Blade Devices, Receptacles, Quad-
PLEX, Commercial/Industrial Grade, 20A
125V, 2-Pole 3-Wire Grounding, 5-20R,
Single Pack, Isolated Ground

By Bryant
Catalog # [21254IGO](#)

Straight Blade Devices, Receptacles, Quad-PLEX,
Commercial/Industrial Grade, 20A 125V, 2-Pole 3-Wire
Grounding, 5-20R, Orange, Single Pack, Isolated Ground

Features

- Quad-PLEX
- Commercial/Industrial Grade
- 20A 125V
- 2-Pole 3-Wire Grounding
- 5-20R

Application

Commercial/Industrial

Specifications


Standards - RoHS Compliance Status	CM
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Nema Rating	5-20R

Conductor

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Current

Amperage Rating	20 A
Voltage Rating Description	125 V

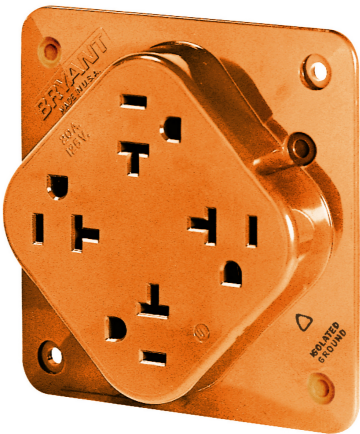

Current Rating	20 A
Voltage Rating	125 V
Wattage	2500
Connectivity	Terminals
Phase	Single Phase
Current / Amperage Rating	20 A

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

General

Color	Orange
Style	4-Receptacle
Series	Straight Blade
OEM Brand Name	Hubbell Bryant
UPC	781786336636
Type	Four Outlet Receptacle
Material - Mounting Hardware	Screw Mounting
Item Type	Quad-Plex
Material	Composite

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)