



Straight Blade Devices, Receptacles, Quad-
PLEX, Commercial/Industrial Grade,
Isolated Ground, 20A 125V, 2-Pole 3-Wire
Grounding, 5-20R, Single Pack

By Bryant
Catalog # [21254IGOL](#)

Straight Blade Devices, Receptacles, Quad-PLEX,
Commercial/Industrial Grade, Isolated Ground, 20A 125V, 2-Pole
3-Wire Grounding, 5-20R, Orange, Single Pack

Features

- Quad-PLEX
- Commercial/Industrial Grade
- Isolated Ground
- 20A 125V
- 2-Pole 3-Wire Grounding

Application

Commercial/Industrial

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No
Nema Rating	5-20R

Conductor


Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Configuration

Number Of Outlets	4
-------------------	---

Current

Current Rating	20 A
Amperage Rating	20 A
Voltage Rating Description	125 V
Phase	Single Phase
Current / Amperage Rating	20 A

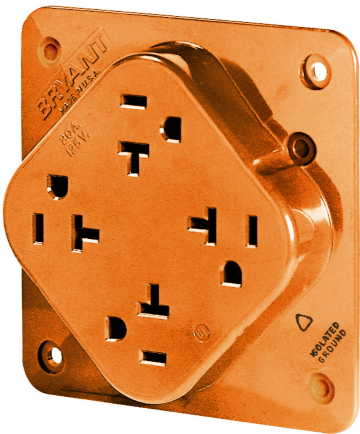

Connectivity
Wattage
Voltage Rating

Wire Leads
2500
125 V

Dimensions

Display Size	Standard Sized Product
Length	4.3 in
Width	4.30 in
Weight	0.45 lb.
Height	0.92 in
Dimensions	4.3 in x 4.30 in x 0.92 in

General

Series	Commercial
OEM Brand Name	Hubbell Bryant
Style	Smooth Face
Color	Orange
Item Type	Quad-Plex
Material - Mounting Hardware	Screw Mounting
Type	Four Outlet Receptacle
Material	Composite
UPC	781786336728

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)