


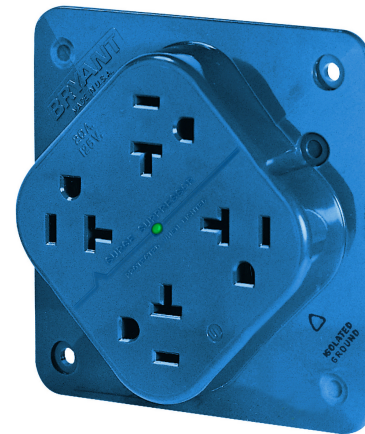

## Straight Blade Devices, Receptacles, QUADPLEX Receptacle, Surge Suppression, Isolated Ground, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R, Blue

By Bryant  
Catalog # 21254SA

Straight Blade Devices, Receptacles, QUADPLEX Receptacle, Surge Suppression, Isolated Ground, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R, Blue



### Features

- QUADPLEX Receptacle
- Surge Suppression
- Isolated Ground
- 20A 125V
- 2-Pole 3-Wire Grounding

### Application

Quad-Plex

### Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No
Nema Rating	5-20R

### Conductor

Number Of Wires	3-Wire
Number Of Poles	2-Pole

### Configuration

Number Of Outlets	4
-------------------	---

### Current

Current Rating	20 A
Amperage Rating	20 A
Frequency Rating	60 Hz
Voltage Rating Description	125 V
Phase	Single Phase
Current / Amperage Rating	20 A
Connectivity	Terminal Screws
Wattage	2500 W
Voltage Rating	125 V

### Dimensions

Display Size	Standard Sized Product
Length	4.3 in
Width	4.30 in
Weight	0.45 lb.
Height	0.92 in
Dimensions	4.3 in x 4.30 in x 0.92 in

### General

Series	Commercial
OEM Brand Name	Hubbell Bryant
Outlet	Straight Blade
Style	Smooth Face
Color	Blue
Item Type	Surge Protection Receptacles
Material - Mounting Hardware	Mounting Screws
Type	Four Outlet Receptacle
Material	Composite
UPC	781786190207

### Logistics

Carton Quantity	10
-----------------	----

### Operational

Response Time	5
Indicator(s) Type	LED Visual Status Indicator
Operating Temperature	32 Deg F to 140 Deg F (0 Deg C to 60 Deg C)

### Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)