



Locking Devices, Bryant Power Interrupting, Industrial, Flanged Receptacle, 60A 600V AC, 3-Pole 4-Wire Grounding, Non-NEMA, Screw Terminal, Yellow

By Bryant
Catalog # 26421

Locking Devices, Bryant Power Interrupting, Industrial, Flanged Receptacle, 60A 600V AC, 3-Pole 4-Wire Grounding, Non-NEMA, Screw Terminal ,Yellow

Features

- Spring loaded safety shutter contains arcing when mating or un-mating devices under load
- Spring loaded safety shutter automatically ejects the plug eliminating contact teasing
- Box terminals in conjunction with stainless steel terminal screws provide maximum termination strength and dependability
- Metallic housing provides protection from damage in harsh environments

Application

Extra Heavy Duty Industrial Specification Grade

Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No

Conductor

Number Of Wires	4-Wire
Wire Size	#18 AWG to #8 AWG
Number Of Poles	3-Pole

Current

Current/Amperage Rating	60 Amp
Description	
Current Rating	60 A

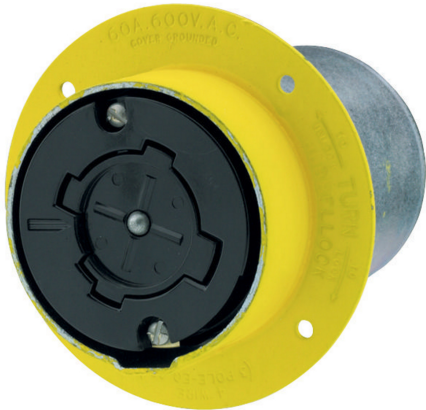

Amperage Rating	60 A
Voltage Rating Description	600V AC
Phase	Multi Phase
Connectivity	Terminal Screws
Voltage Rating	600 VAC

Dimensions

Display Size	Standard Sized Product
Length	4.12 in
Width	4.12 in
Height	4.53 in
Dimensions	4.12 in x 4.12 in x 4.53 in

General

OEM Brand Name	Hubbell Bryant
Style	Grounding
Color	Yellow
Item Type	60A Flanged Single Receptacle
Material - Mounting Hardware	Screw Mounting
Type	Flanged Receptacle
Material	Composite
UPC	781786584211

Logistics

Carton Quantity	5
-----------------	---

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)