



Locking Devices, Locking Devices,  
Industrial, Flanged Inlet, 50A 250V  
DC/600V AC, 2-Pole 3-Wire Grounding,  
Non-NEMA, Screw Terminal, Galvanized

By Bryant  
Catalog # 3767

Locking Devices, Locking Devices, Industrial, Flanged Inlet, 50A  
250V DC/600V AC, 2-Pole 3-Wire Grounding, Non-NEMA, Screw  
Terminal, Galvanized

Features

- Flanged Inlet with Lift Cover and Gasket
- 50A 250V DC/600V AC
- 2-Pole 3-Wire Grounding
- Non-NEMA
- Screw Terminal

Application

Extra Heavy Duty Industrial

Specifications


|                          |                                                    |
|--------------------------|----------------------------------------------------|
| Environmental Conditions | Indoor Dry Unless Protected By<br>Additional Means |
| EU RoHS Indicator        | No                                                 |

Conductor

|                 |                   |
|-----------------|-------------------|
| Number Of Wires | 3-Wire            |
| Wire Size       | #18 AWG to #8 AWG |
| Number Of Poles | 2-Pole            |

Current

|                            |                             |
|----------------------------|-----------------------------|
| Dielectric Strength        | Withstands 3000V Minimum in |
| Current/Amperage Rating    | 50 Amp                      |
| Description                |                             |
| Current Rating             | 50 A                        |
| Amperage Rating            | 50 A                        |
| Voltage Rating Description | 250 VDC/600 VAC             |
| Connectivity               | Pressure Terminal Screws    |
| Voltage Rating             | 250 VDC/600 VAC             |

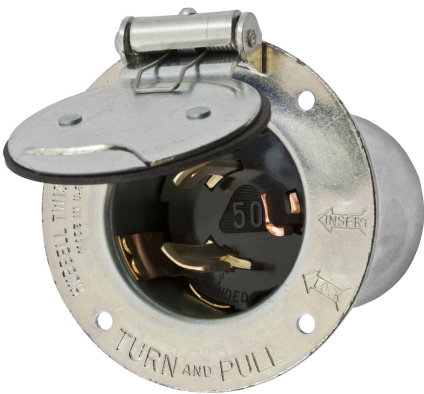

Dimensions

|              |                             |
|--------------|-----------------------------|
| Display Size | Standard Sized Product      |
| Length       | 2.77 in                     |
| Width        | 3.50 in                     |
| Height       | 3.50 in                     |
| Dimensions   | 2.77 in x 3.50 in x 3.50 in |

General

|                              |                                               |
|------------------------------|-----------------------------------------------|
| OEM Brand Name               | Hubbell Bryant                                |
| Style                        | Extra Heavy Duty                              |
| Color                        | Metallic                                      |
| Item Type                    | 50A Male Flanged Inlet-For<br>Replacement Use |
| Insulation                   | Insulated Body                                |
| Material - Mounting Hardware | Screw Mounting                                |
| Type                         | Flanged Inlet                                 |
| Material                     | Composite                                     |
| UPC                          | 781786652705                                  |

Logistics

|                 |    |
|-----------------|----|
| Carton Quantity | 10 |
|-----------------|----|

Operational

|                    |                                                                                                                                 |
|--------------------|---------------------------------------------------------------------------------------------------------------------------------|
| Temperature Rating | <ul style="list-style-type: none"><li>• Maximum Continuous: 75° C</li><li>• Minimum Continuous: -40° C<br/>w/o impact</li></ul> |
|--------------------|---------------------------------------------------------------------------------------------------------------------------------|

Product Assets

[Catalog \[English\]](#)  
[Catalog Page \[English\]](#)