


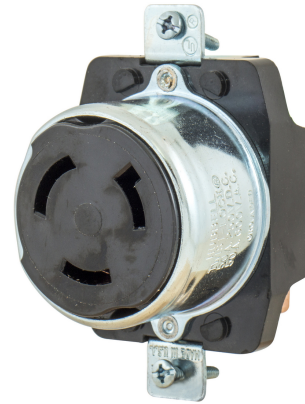

Locking Devices, Locking Devices, Industrial, Flush Receptacle, 50A 250V DC/600V AC, 2-Pole 3-Wire Grounding, Non- NEMA, Screw Terminal, Black

By Bryant
Catalog # 3771



Locking Devices, Locking Devices, Industrial, Flush Receptacle, 50A 250V DC/600V AC, 2-Pole 3-Wire Grounding, Non- NEMA, Screw Terminal, Black

Features

- Flush Receptacle
- 50A 250V DC/600V AC
- 2-Pole 3-Wire Grounding
- Non- NEMA
- Screw Terminal

Application

Extra Heavy Duty Industrial Specification Grade

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No
Standards - RoHS Compliance Status	CM

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #10 AWG
Number Of Poles	2-Pole

Current

Current/Amperage Rating	50 Amp
Description	
Current Rating	50 A
Amperage Rating	50 A
Voltage Rating Description	250 VDC/600 VAC
Phase	Single Phase

Connectivity
Voltage Rating

Pressure Terminal Screws
250 VDC/600 VAC

Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	2.12 in
Height	2.44 in
Dimensions	3.28 in x 2.12 in x 2.44 in

General

OEM Brand Name	Hubbell Bryant
Style	Extra Heavy Duty
Color	Black
Item Type	50A Single Armored Heavy Duty Receptacle-For Replacement Use
Material - Mounting Hardware Type	Screw Mounting Receptacle
Material	Composite
UPC	781786652903

Logistics

Carton Quantity 10

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)