




# Locking Devices, Locking Devices, Marine Grade, Duplex Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, L5-15R, Screw Terminal, Yellow

By Bryant  
Catalog # [4700DRCR](#)

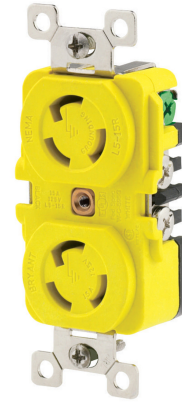

Locking Devices, Locking Devices, Marine Grade, Duplex Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, L5-15R, Screw Terminal, Yellow

## Features

- Reinforced thermoplastic construction
- Single piece, all brass contacts
- Single point break-off tabs
- Mounting strap tabs lock the body and base together

## Application

Extra Heavy Duty Industrial Specification Grade

## Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Nema Rating	L5-15R

## Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #8 AWG
Number Of Poles	2-Pole

## Current

Current/Amperage Rating	15 Amp
Description	
Current Rating	15 A
Amperage Rating	15 A
Voltage Rating Description	125V

Phase	Single Phase
Connectivity	Terminal Screws
Voltage Rating	125 V

## Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	1.70 in
Height	0.93 in
Dimensions	3.28 in x 1.70 in x 0.93 in

## General

OEM Brand Name	Hubbell Bryant
Style	Duplex Receptacle
Item Type	15A Duplex Receptacle
Material - Mounting Hardware	Screw Mounting Receptacle
Type	Receptacle
Material	Composite
UPC	781786002043

## Logistics

Carton Quantity	10
-----------------	----

## Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)