




Straight Blade Devices, Locking Devices, Industrial, Combination Face Duplex Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, L5-15R, Screw Terminal

By Bryant
Catalog # [4792DR](#)

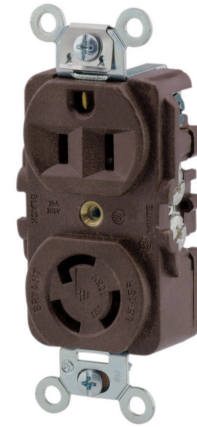

Straight Blade Devices, Locking Devices, Industrial, Combination Face Duplex Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, L5-15R, Screw Terminal, Reinforced thermoplastic polyester, 1 feed, 1 return, Brown

Features

- Industrial
- Combination Face Duplex Receptacle
- 15A 125V
- 2-Pole 3-Wire Grounding
- L5-15R

Application

Extra Heavy Duty Industrial Specification Grade

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Standards - RoHS Compliance	CM
Status	
Nema Rating	5-15R, L5-15R

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Current

Current Rating	15 A
Amperage Rating	15 A
Voltage Rating Description	125 V
Phase	Single Phase

Current / Amperage Rating	15 A
Connectivity	Back and Side Wired
Wattage	3750
Voltage Rating	125 V

Dimensions

Display Size	Standard Sized Product
Length	4.06 in
Width	1.69 in
Weight	0.3 lb.
Height	1.19 in
Dimensions	4.06 in x 1.69 in x 1.19 in

General

Series	Heavy Duty
OEM Brand Name	Hubbell Bryant
Style	Finder Groove Face
Color	Brown
Item Type	Traditional Duplex
Material - Mounting Hardware	Screw Mounting
Type	Combination Receptacle
UPC	781786657069

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)