


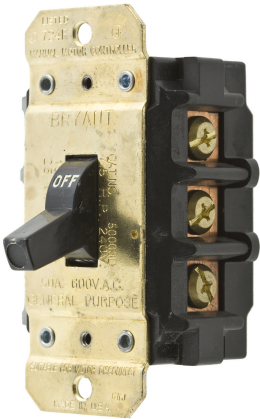

Disconnect Switches, Three Pole, 40A 600V AC, Black

By Bryant
Catalog # 50003D

Disconnect Switches, Three Pole, 40A 600V AC, Black



Features

- 40A 600V AC
- Black

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes

Conductor

Number Of Poles	3 Pole
-----------------	--------

Current

Current Rating	50 A
Amperage Rating	50 A
Voltage Rating Description	600V AC kV
Phase	Three Phase
Current / Amperage Rating	50 A
Connectivity	Pressure Terminal Screws
Wattage	30000
Voltage Rating	600V AC kV

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Force Related

Load Capacity	Inductive
---------------	-----------

General

Series	Standard Toggle
OEM Brand Name	Hubbell Bryant
Style	Motor Controller/Disconnect
Item Type	Open Switch
Material - Mounting Hardware	Screw Mounting
Type	Side Wire
UPC	781786631687

Logistics

Carton Quantity	10
-----------------	----

Operational

Operating Cycles	10,000 Cycles Minimum
Operating Temperature	Minimum Continuous -40 Deg C without Impact

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)