



## Straight Blade Devices, Receptacles, Single, Commercial/Industrial Grade, 2-Pole 3-Wire Grounding, 15A 250V, 6-15R, Brown, Single Pack

By Bryant  
Catalog # 5661

Straight Blade Devices, Receptacles, Single,  
Commercial/Industrial Grade, 2-Pole 3-Wire Grounding, 15A  
250V, 6-15R, Brown, Single Pack

### Features

- Single
- Commercial/Industrial Grade
- 2-Pole 3-Wire Grounding
- 15A 250V
- 6-15R

### Application

Extra Heavy Duty Industrial Specification Grade

### Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Standards - RoHS Compliance Status	CM
Nema Rating	6-15R

### Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

### Current

Current Rating	15 A
Amperage Rating	15 A
Voltage Rating Description	250 V
Phase	Single Phase
Current / Amperage Rating	15 A

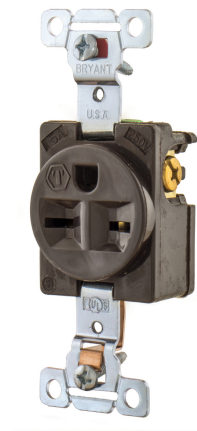

Connectivity	Back and Side Wired
Wattage	3750
Voltage Rating	250 V

### Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	1.38 in
Weight	0.1 lb.
Height	0.91 in
Dimensions	3.28 in x 1.38 in x 0.91 in

### General

Series	Extra Heavy Duty
OEM Brand Name	Hubbell Bryant
Style	Finder Groove Face
Color	Brown
Item Type	Single
Material - Mounting Hardware Type	Screw Mounting Single Receptacle
UPC	781786625907

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)