



Switches and Lighting Controls, Industrial Grade, Toggle Switches, Manual Motor Controllers, Three Pole, 60A 600V AC, Front Wired, Black

By Bryant
Catalog # 60003FWD

Switches and Lighting Controls, Industrial Grade, Toggle Switches, Manual Motor Controllers, Three Pole, 60A 600V AC, Front Wired, Black

Features

- Toggle
- Manual Motor Controllers
- Three Pole
- 60A 600V AC
- Front Wired

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes


Conductor

Number Of Poles	3 Pole
-----------------	--------

Current

Current Rating	60 A
Amperage Rating	60 A
Voltage Rating Description	600V AC kV
Phase	Three Phase
Current / Amperage Rating	60 A
Connectivity	Pressure Terminal Screws
Wattage	36000
Voltage Rating	600V AC kV

Dimensions

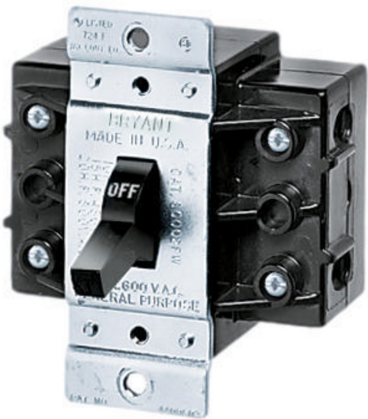

Display Size	Standard Sized Product
--------------	------------------------

Force Related

Load Capacity	Inductive
---------------	-----------

General

Series	Standard Toggle
OEM Brand Name	Hubbell Bryant
Style	Motor Controller/Disconnect
Item Type	Open Switch
Material - Mounting Hardware	Screw Mounting
Type	Front Wire
UPC	781786631755

Logistics

Carton Quantity	10
-----------------	----

Operational

Operating Cycles	10,000 Cycles Minimum
Operating Temperature	Minimum Continuous -40 Deg C without Impact

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)