



## Locking Devices, Marine Grade, Male Plug, 30A 125V, 2-Pole 3-Wire Grounding, L5-30P, Screw Terminal, Yellow, Corrosion Resistant

By Bryant  
Catalog # [70530NPCR](#)

Locking Devices, Marine Grade, Male Plug, 30A 125V, 2-Pole 3-Wire Grounding, L5-30P, Screw Terminal, Yellow, Corrosion Resistant

### Features

- Nickel-plated copper-alloy metallic components
- Molded of impact/chemical resistant high-visibility yellow nylon
- Stainless steel screws
- Triple Gripper® cord grip on plugs and connectors which feature three captive assembly screws to automatically tighten cord grip
- Individual wire pockets with clamp-type terminals

### Application

Extra Heavy Duty Industrial

### Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Nema Rating	L5-30P

### Conductor


Number Of Wires	3-Wire
Wire Size	#18 AWG to #8 AWG
Number Of Poles	2-Pole

### Configuration

Cord Type	All Listed Portables
-----------	----------------------

### Current

Current/Amperage Rating	30 Amp
Description	
Current Rating	30 A

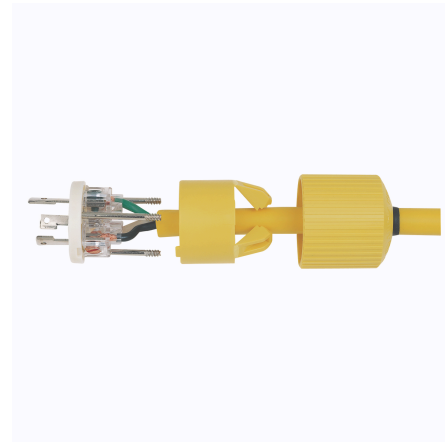

Amperage Rating	30 A
Voltage Rating Description	125 V
Phase	Single Phase
Connectivity	Screw Terminals
Voltage Rating	125 V

### Dimensions

Display Size	Standard Sized
Length	2.13 in
Width	2.13 in
Height	2.86 in
Dimensions	2.13 in x 2.13 in x 2.86 in

### General

OEM Brand Name	Hubbell Bryant
Style	Internal Cord Clamp
Color	Corrosion Resistant
Item Type	30A Triple Gripper Nylon Plug
Material - Mounting Hardware	Cord Mounted
Type	Plugs
Material	Composite
UPC	781786688827

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)