



Locking Devices, Industrial, Panel Mount
Receptace, 15A 250V, 2-Pole 3-Wire
Grounding, L6-15R, Screw Terminal, Black,
1.94" Mounting

By Bryant
Catalog # [7061594](#)

Locking Devices, Industrial, Panel Mount Receptace, 15A 250V, 2-
Pole 3-Wire Grounding, L6-15R, Screw Terminal, Black, 1.94"
Mounting

Features

- Panel Mount Receptacle
- 15A 250V
- 2-Pole 3-Wire Grounding
- L6-15R
- Screw Terminal

Application

Extra Heavy Duty Industrial Specification Grade

Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Nema Rating	L6-15R

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #8 AWG
Number Of Poles	2-Pole

Current

Phase	Single Phase
Current/Amperage Rating	15 Amp
Description	
Connectivity	Terminal Screws
Current Rating	15 A

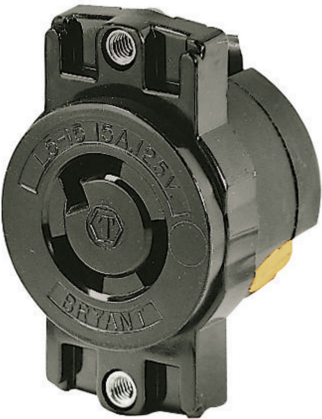

Amperage Rating	15 A
Voltage Rating Description	250V
Voltage Rating	250 V

Dimensions

Display Size	Standard Sized Product
Width	1.41 in
Height	1.09 in
Length	2.38 in
Dimensions	2.38 in x 1.41 in x 1.09 in

General

Item Type	15A Panel Mount Single Receptacle
Material - Mounting Hardware Type	Screw Mounting Receptacle
OEM Brand Name	Hubbell Bryant
Material	Composite
UPC	781786616356
Style	Panel Mount

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)