



## Locking Devices, Industrial, Flush Receptacle, 30A 125/250V, 3-Pole 3-Wire Non-Grounding, L10-30R, Screw Terminal, Black

By Bryant  
Catalog # [71030FR](#)

Locking Devices, Industrial, Flush Receptacle, 30A 125/250V, 3-Pole 3-Wire Non-Grounding, L10-30R, Screw Terminal, Black

### Features

- Combination back and side wiring terminals accept #14 through #8 AWG solid or stranded conductors
- Heavy duty mounting straps are nickel-plated to resist corrosion, wide width design assures secure assembly
- NEMA rating and configuration are molded into face for easy identification
- One-piece, rivetless copper-alloy contact design reduces heat buildup and provides secure blade retention

### Application

Extra Heavy Duty Industrial Specification Grade

### Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Standards - RoHS Compliance Status	CM
Nema Rating	L10-30R

### Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #8 AWG
Number Of Poles	3-Pole

### Current

Current/Amperage Rating	30 Amp
Description	

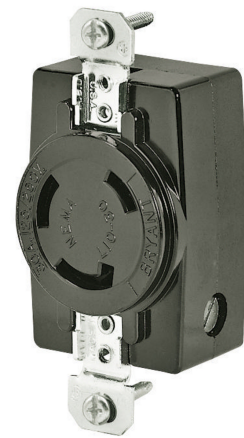

Current Rating	30 A
Amperage Rating	30 A
Voltage Rating Description	125/250V AC
Phase	Single Phase
Connectivity	Terminal Screws
Voltage Rating	125/250 VAC

### Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	1.70 in
Height	1.24 in
Dimensions	3.28 in x 1.70 in x 1.24 in

### General

OEM Brand Name	Hubbell Bryant
Style	Single Receptacle
Item Type	30A Single Nylon Receptacle
Material - Mounting Hardware	Screw Mounting
Type	Receptacle
Material	Composite
UPC	781786692633

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)