



Locking Devices, Industrial, Receptacle, 15A 125V/10A 250V, 3-Pole 3-Wire Non Grounding, Non-NEMA, Screw Terminal, Black

By Bryant
Catalog # 7582

Locking Devices, Industrial, Receptacle, 15A 125V/10A 250V, 3-Pole 3-Wire Non Grounding, Non-NEMA, Screw Terminal, Black

Features

- Reinforced thermoplastic construction
- Single piece, all brass contacts
- All terminals are back and side wired
- Brass mounting strap with stainless steel grounding clip

Application

Extra Heavy Duty Industrial Specification Grade

Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No
Nema Rating	Non-NEMA

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #8 AWG
Number Of Poles	3-Pole

Current

Current/Amperage Rating	10 Amp
Description	
Current Rating	10 A
Amperage Rating	10 A
Voltage Rating Description	250V
Phase	Single Phase

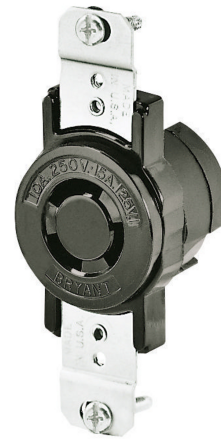

Connectivity
Voltage Rating

Terminal Screws
250 V

Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	1.38 in
Height	1.41 in
Dimensions	3.28 in x 1.38 in x 1.41 in

General

OEM Brand Name	Hubbell Bryant
Style	Single Receptacle
Item Type	10A Single Receptacle Non-NEMA
Material - Mounting Hardware Type	Screw Mounting Receptacle
Material	Composite
UPC	781786629493

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)