




Straight Blade Devices, Receptacles, Flush Mount Single, Industrial Grade, 4-Pole 4-Wire Non-Grounding, 60A 3-Phase 120/208V AC, 18-60R, Single Pack

By Bryant
Catalog # [8360FR](#)

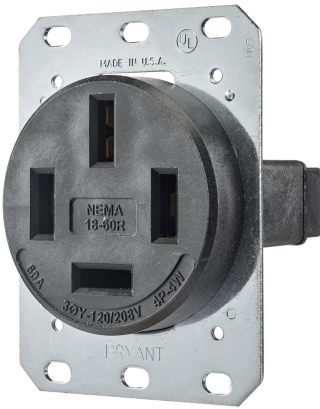

Straight Blade Devices, Receptacles, Flush Mount Single, Industrial Grade, 4-Pole 4-Wire Non-Grounding, 60A 3-Phase 120/208V AC, 18-60R, Black, Single Pack

Features

- Flush Mount Single
- Industrial Grade
- 4-Pole 4-Wire Non-Grounding
- 60A 3-Phase 120/208V AC
- 18-60R

Application

Industrial Grade

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Nema Rating	18-60R
Industry Standard(s)	WR Rating

Conductor

Number Of Wires	4-Wire
Wire Size	#6 AWG
Number Of Poles	4-Pole

Current

Amperage Rating	60 A
Voltage Rating Description	3 Phase 120/208 VAC
Current Rating	60 A
Voltage Rating	Three Phase 120/208 VAC
Wattage	15000

Connectivity	Pressure Terminal Screws
Phase	Single Phase
Current / Amperage Rating	60 A

Dimensions

Length	3.68 in
Display Size	Standard Sized Product
Weight	0.65 lb.
Height	2.12 in
Width	2.25 in
Dimensions	3.68 in x 2.25 in x 2.12 in

General

Color	Black
Style	Smooth Face
Series	Heavy Duty
OEM Brand Name	Hubbell Bryant
UPC	781786673403
Type	Single Receptacle
Material - Mounting Hardware	Screw Mounting
Item Type	Single

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)